

# Powerful at every turn


Thermo Scientific™ General Purpose Pro Centrifuges



## New touchscreen technology

**Easy menu access:** no more scrolling

**Precool function:** centrifuge can be "at temp" before run

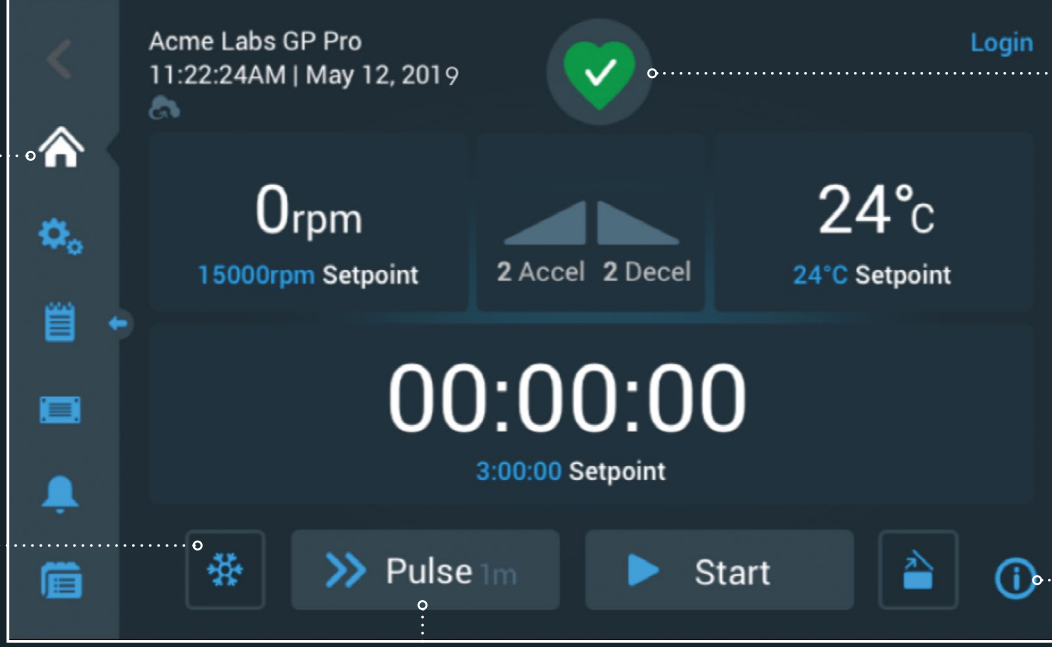

**Pulse button:** customizable one-touch quick spins

**Home screen**

**Centrifuge health:** preventative maintenance alerts for less downtime

**Help menu:** virtual manual provides quick solutions



## New Thermo Scientific™ Auto-Lock™ II rotor exchange



Quick switch between applications



Safely switch rotors in as few as 3 seconds



New soft unlock feature



No tools required

## Thermo Scientific™ Fiberlite™ carbon fiber rotors

- Lightweight carbon fiber
- Outstanding durability
- Corrosion- and fatigue-resistant
- Backed by a 15-year limited warranty



## Thermo Scientific™ ClickSeal™ biocontainment lids



Glove friendly



One-handed closure



Biocontainment certifications



Designed for right- or left-handed operation

## Capacity and performance

- Spin up to 40 conical tubes (50 mL) or 196 blood sample tubes
- Compact footprint
- Improved sample safety
- Greater sample reproducibility
- Choose between 1.6 L and 4 L floor or bench models

## Improved ergonomics



Loading height decreased by 1.2 cm (0.5 in.)



Less effort required to close lid



Lid gripper height decreased by 5.1 cm (2 in.)